

# FL2-6PBSC605R

---

FL2000 Fiber Optic Adapter-pack, with 12 singlemode LC/APC adapters, with pigtails, 5 meters

## Product Classification

<b>Regional Availability</b>	North America
<b>Product Type</b>	Fiber adapter pack with pigtails
<b>Product Series</b>	FL2000

## General Specifications


<b>Application</b>	For use with FL2 panels
<b>Adapter Color</b>	Green
<b>Adapters, quantity, front</b>	6
<b>Body Style</b>	Duplex   Straight orientation
<b>Color, front</b>	Putty white
<b>Interface</b>	LC/APC
<b>Pigtail Assembly Type</b>	Color-coded, 900 $\mu$ m   Pigtail bundle
<b>Pigtails Included, quantity</b>	12
<b>Total Fibers, quantity</b>	12
<b>Total Ports, quantity, front</b>	12

## Dimensions

<b>Height</b>	27.94 mm   1.1 in
<b>Width</b>	149.86 mm   5.9 in
<b>Pigtail Length</b>	5 m   16.404 ft

## Ordering Tree

# FL2-6PBSC605R

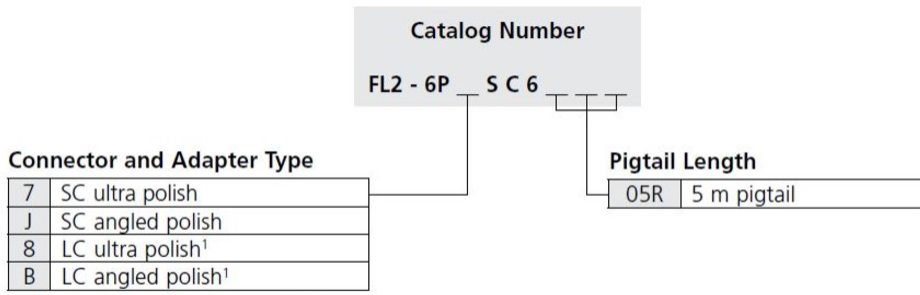

<sup>1</sup> LC 6paks are loaded with 12-fiber pigtails

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	OS2
<b>Insertion Loss, maximum</b>	0.35 dB
<b>Return Loss, minimum</b>	65 dB

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Bag   Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

