


LSA-PLUS® Comprotect Overvoltage Plug, 2/1, CP NTP GB180C1

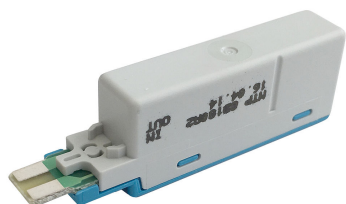

Product Classification

Regional Availability	EMEA
Product Type	Overvoltage plug
Product Brand	LSA-PLUS®

General Specifications

Transmission Standards	DIN EN 60068-2-1 DIN EN 60068-2-2/3 DIN EN 60068-2-6 ITU-T K.12
-------------------------------	---

Dimensions

Height	12.954 mm 0.51 in
Width	7.874 mm 0.31 in
Length	43.434 mm 1.71 in

Electrical Specifications

Capacitance	5 pF
Current Rating, maximum	0.12 A
dc Resistance, maximum	1 ohm
Insulation Resistance, minimum	1000 MOhm
Safety Voltage Rating	180 V

Environmental Specifications

Operating Temperature	-20 °C to +60 °C (-4 °F to +140 °F)
Storage Temperature	-40 °C to +80 °C (-40 °F to +176 °F)
Environmental Space	Indoor

Packaging and Weights

Packaging quantity	10
Packaging Type	Bag Box

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

