


FGS-MSHS-STOR-B

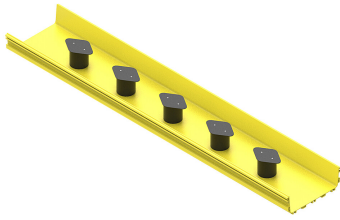

FiberGuide® Slack Storage Straight Section, 4x6in, Yellow

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Solid straight with slack storage
Product Brand	FiberGuide®
Product Series	FGS

General Specifications

Product Feature	Snap-together design
Color	Yellow
Orientation	Horizontal
Section Type	Straight Section

Dimensions

Length	1829 mm 72.008 in
System Dimensions	102 mm x 152 mm (4 in x 6 in)

Ordering Tree

FGS-MSHS-STOR-B

9	10	11	
FGS	B	- MSHS - F	10

Section Color

9	empty	yellow
	B	black

Section Length

11	empty	6 ft
	10	10 ft
	12	12 ft

Section Size

10	A	4 x 4 in
	B	4 x 6 in
	C	2 x 2 in
	D	4 x 4 in, slotted duct, 2 in slot spacing
	F	4 x 12 in
	F-CF	4 x 12 in, with center divider
	G	2 x 6 in
	H	4 x 24 in
	K	2 x 4 in, slotted duct, 2 in slot spacing
	STOR-B	4 x 6 in, with slack storage spools
	STOR-G	2 x 6 in, with slack storage spools
	STOR-F	4 x 12 in, with slack storage spools

Material Specifications

Material Type Engineering Thermoplastic

Environmental Specifications

Flammability Rating CSA S143 | UL 2024 | UL 94 V-0

Halogen Characteristics Blue Angel | TCO '99 | WEEE

Safety Standard CSA | UL

Packaging and Weights

Weight, net 6.3 kg | 13.889 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant



