


294699

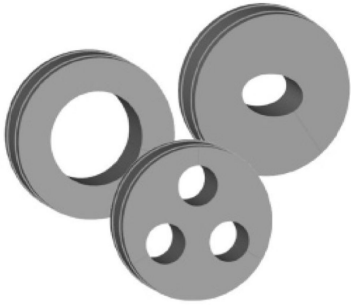

Cushion Insert with 3 holes for 7/8 in corrugated coaxial cable

Product Classification

Product Type	Cushion insert
Product Brand	I-Line
Ordering Note	CommScope® non-standard product

General Specifications

Cable Type	Corrugated
Cables per Cushion	3
Color	Black

Dimensions

Height	82.55 mm 3.25 in
Length	25.4 mm 1 in
Nominal Size	7/8 in

Material Specifications

Material Type	EPDM rubber
----------------------	-------------

Environmental Specifications

UV Resistance Test Method	MIL-STD-810E, Procedure 11, Method 505
UV Resistance, minimum with no degradation	≥1000 hours
Weather Resistance Test Method	04AS00-03.9.0 IEC 60529:2001, IP66

Packaging and Weights

Height, packed	170.18 mm 6.7 in
-----------------------	--------------------

294699

Width, packed	129.54 mm 5.1 in
Length, packed	99.06 mm 3.9 in
Included	Cushion
Packaging quantity	1
Weight, gross	0.8 kg 1.764 lb

Regulatory Compliance/Certifications

Agency	Classification
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant