


MTC401548HC

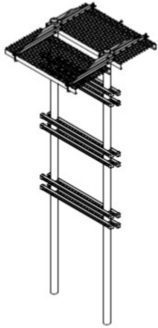

H-Frame with Ice Canopy, 4ft long with 2 Posts

Product Classification

Product Type Ice canopies and shields

Dimensions

Height 4,076.7 mm | 160.5 in

Width 1,460.5 mm | 57.5 in

Length 1,219.2 mm | 48 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Hardware | Ice shield | Legs | Unistrut

Packaging quantity 1

Weight, net 162.5 kg | 358.251 lb

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

 
Designed, manufactured and/or distributed under this quality management system



Included Products

MF-130 – Direct Burial Pipe Column, 13 ft 4 in

MF-130



Direct Burial Pipe Column, 13 ft 4 in

Product Classification

Product Type Pipe column

General Specifications


Application Direct burial
Mounting Waveguide bridge support bracket
Pipe, quantity 1

Dimensions

Height 4064 mm | 160 in
Width 88.9 mm | 3.5 in
Length 88.9 mm | 3.5 in
Pipe Length 4,053.84 mm | 159.6 in
Pipe Outer Diameter 88.9 mm | 3.5 in

MF-130

Outline Drawing

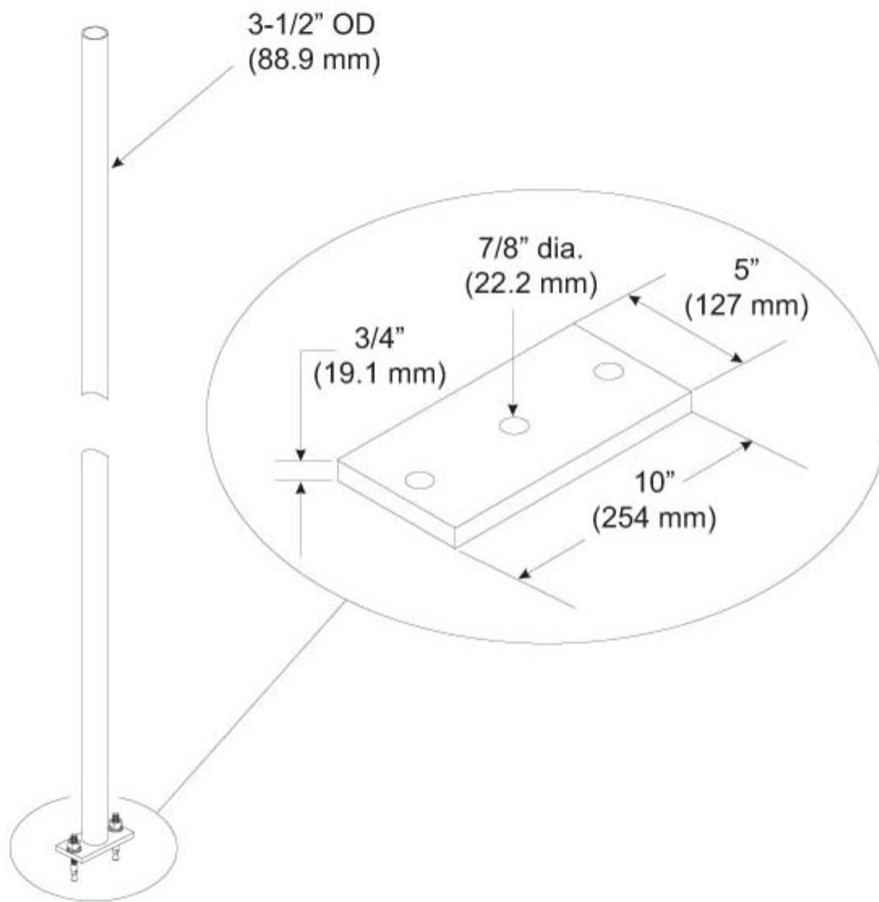

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Anchors | Pipe

Packaging quantity 1

Weight, net 45.8 kg | 100.972 lb

Regulatory Compliance/Certifications

Agency **Classification**

MF-130

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

