


ALGLGUCCH

Base Product

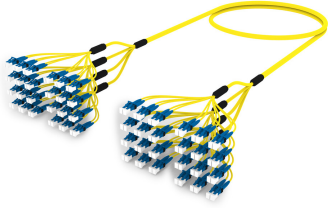

Ultra Low Loss ULL TeraSPEED® LC/APC to Unconnectorized Ruggedized fanout Cable, 48-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Blue

Color, connector A

Green

Color, boot B

Blue

Color, connector B

Blue

Construction Type

Stranded

Furcation Color

Yellow

Interface, Connector A

LC/APC

Interface Feature, connector A

ULL

Interface, Connector B

Unterminated

Interface Feature, connector B

ULL

Jacket Color

Yellow

Fibers per Subunit, quantity

12

Total Fibers, quantity

48

Dimensions

Cable Assembly Length Range (m)

3 – 305

Cable Assembly Length Range (ft)

10 – 999

ALGLGUCCH

Ordering Tree



Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	Dca
Environmental Space	Indoor Plenum

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant



Included Products

- 760242055
P-048-MP-8G-F12YL/20T – Fiber indoor cable, Plenum MPO Trunk, 48 fiber multi-unit with 12 fiber subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color