


# 9-737858-2 | AS-10-Splice-Dry

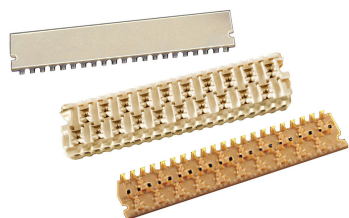

## AMP STACK™ IV Connector Splice Kit, dry, 10-pair

### Product Classification

#### Regional Availability

Asia | Australia/New Zealand | EMEA | Latin America | North America

#### Product Type

Connector kit

#### Product Brand

AMP STACK™

#### Product Series

AMP STACK

#### Ordering Note

Minimum order quantity, 120 parts

### General Specifications

#### Color

Gold ivory | Transparent

#### Connector Sealant

Dry

#### Connector Splicing Type

Straight (In-line)

#### Pairs, quantity

10

### Dimensions

#### Compatible Insulated Conductor Diameter, maximum

1.96 mm | 0.077 in

#### Compatible Conductor Gauge, solid

26–19 AWG

### Material Specifications

#### Contact Base Material

Phosphor Bronze

#### Contact Plating Material

Tin

#### Material Type

Glass filled polycarbonate

### Environmental Specifications

#### Environmental Space

Outdoor

# 9-737858-2 | AS-10-Splice-Dry

---

## Packaging and Weights

<b>Included</b>	Base with covers
<b>Packaging quantity</b>	12
<b>Packaging Type</b>	Bag   Box

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant

