


760018820 | 6 FIBER BREAKOUT KIT

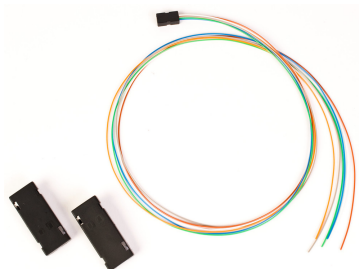

6 Fiber Breakout Kit, loose tube

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Fiber breakout kit, rectangular

General Specifications

Color	Black
Compatible Interface	LC LC, keyed SC ST

Dimensions

Height	7.62 mm 0.3 in
Width	17.78 mm 0.7 in
Length	43.18 mm 1.7 in
Tube Length	609.6 mm 24 in
Tube Inner Diameter	500 µm
Tube Outer Diameter	900 µm

Material Specifications

Material Type, body	Acrylonitrile butadiene styrene (ABS)
Material Type, tubing	Thermoplastic elastomer (TPE)

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
------------------------------	--------------------------------------

Packaging and Weights

Included	Breakout unit Instruction sheet Six buffer tubes, 24 in x 900 µm Snap together housing
Packaging quantity	1

760018820 | 6 FIBER BREAKOUT KIT

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

