


# L-RD

---

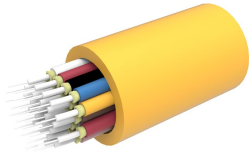

Fiber Optic Cable, Indoor Zero Halogen, CPR-only flame rated, Retractable Dielectric

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber indoor cable
<b>Product Series</b>	L-RD

## General Specifications

<b>Cable Type</b>	Stranded indoor
<b>Construction Type</b>	Non-armored
<b>Subunit Type</b>	Gel-free

## Environmental Specifications

<b>Installation temperature</b>	-10 °C to +50 °C (+14 °F to +122 °F)
<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Storage Temperature</b>	-40 °C to +70 °C (-40 °F to +158 °F)
<b>Cable Qualification Standards</b>	IEC 60794-1-2
<b>Environmental Space</b>	Low Smoke Zero Halogen (LSZH)

## \* Footnotes

**Operating Temperature** Specification applicable to non-terminated bulk fiber cable