


# FDC-AT-S38-02018

---

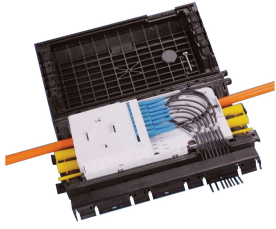

FDC Fiber Optic Splice/Patch Closure, Gel Cable Sealing, 8 SC/APC Adapters, 24 fusion splices

## Product Classification

<b>Regional Availability</b>	Asia   EMEA   Latin America
<b>Product Type</b>	In-line, rectangular fiber closure
<b>Product Series</b>	FDC

## General Specifications

<b>Cable Ports Quantity, total</b>	6 round ports
<b>Cable Sealing Type</b>	Compressed gel
<b>Closure Sealing Type</b>	Hinged with latch
<b>Closure Style</b>	In-line
<b>Color</b>	Black
<b>Mounting</b>	Manhole   Pedestal   Strand   Wall
<b>Port Type</b>	SC/APC
<b>Port, quantity</b>	8
<b>Splice Tray Included, quantity</b>	1
<b>Splice Tray Type Included</b>	24-way, heat shrink
<b>Splitter Type</b>	No splitter
<b>Splitter, quantity</b>	0

## Dimensions

<b>Height</b>	83 mm   3.268 in
<b>Width</b>	160 mm   6.299 in
<b>Length</b>	270 mm   10.63 in

## Material Specifications

<b>Material Type</b>	Rugged polymer
----------------------	----------------

# FDC-AT-S38-02018

---

## Environmental Specifications

**Environmental Space** Above ground | Below ground

## Packaging and Weights

**Included** Splitter (1)

**Packaging quantity** 1

**Packaging Type** Box | Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

