


# FE-18184

---

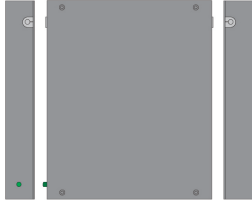

HELIAX® Outdoor Excess Cable Enclosure, 18 in x 18 in x 4 in

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Outdoor junction box
<b>Product Brand</b>	HELIAX®

## General Specifications

<b>Application</b>	Accepts 30 m of excess fiber trunk cable
<b>Cable Entry, quantity, maximum, left</b>	1
<b>Cable Entry, quantity, maximum, right</b>	1
<b>Color</b>	Gray
<b>Mounting</b>	Pipe, 76.2 mm (3 in) OD   Wall

## Dimensions

<b>Height</b>	465.582 mm   18.33 in
<b>Width</b>	457.2 mm   18 in
<b>Depth</b>	101.6 mm   4 in

## Material Specifications

<b>Material Type</b>	Aluminum
----------------------	----------

## Environmental Specifications

<b>Environmental Space</b>	Indoor   Outdoor
<b>Qualification Standards</b>	IEC 60529:2001, IP64

## Packaging and Weights

<b>Included</b>	Mounting kit
<b>Weight, net</b>	4.463 kg   9.84 lb

## Regulatory Compliance/Certifications

**Agency****Classification**

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

