

MC-SA18-B

Stand-off Arm with U-bolts, 18 in



Product Classification

Product Type Support arms for ring mount

General Specifications

Mounting Ring mount

Pipe, quantity 0

Dimensions


Height 254 mm | 10 in

Width 254 mm | 10 in

Length 457.2 mm | 18 in

Stand-off Distance 457.2 mm | 18 in

Outline Drawing

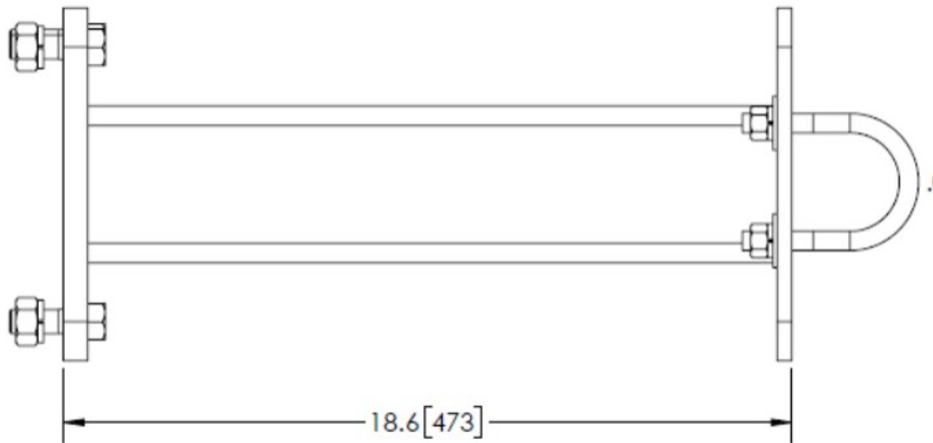

MC-SA18-B

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact steelproducts@commscope.com or call 800-255-1479

Wind Rating Criteria One 72 in x 8 in panel antenna per sector

Wind Rating Test Method TIA/EIA-222-G

Packaging and Weights

Included Hardware | Stand-off arms | U-bolts

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code