


MC-SA24-B

Stand-off Arm -24 in with U-bolts for 2-3/8" Pipe

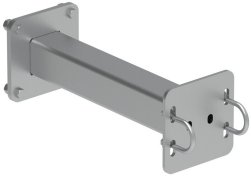

Product Classification

Product Type Support arms for ring mount

General Specifications

Mounting Ring mount

Pipe, quantity 0

Dimensions

Height 254 mm | 10 in


Width 254 mm | 10 in

Length 609.6 mm | 24 in

Stand-off Distance 609.6 mm | 24 in

Outline Drawing

MC-SA24-B

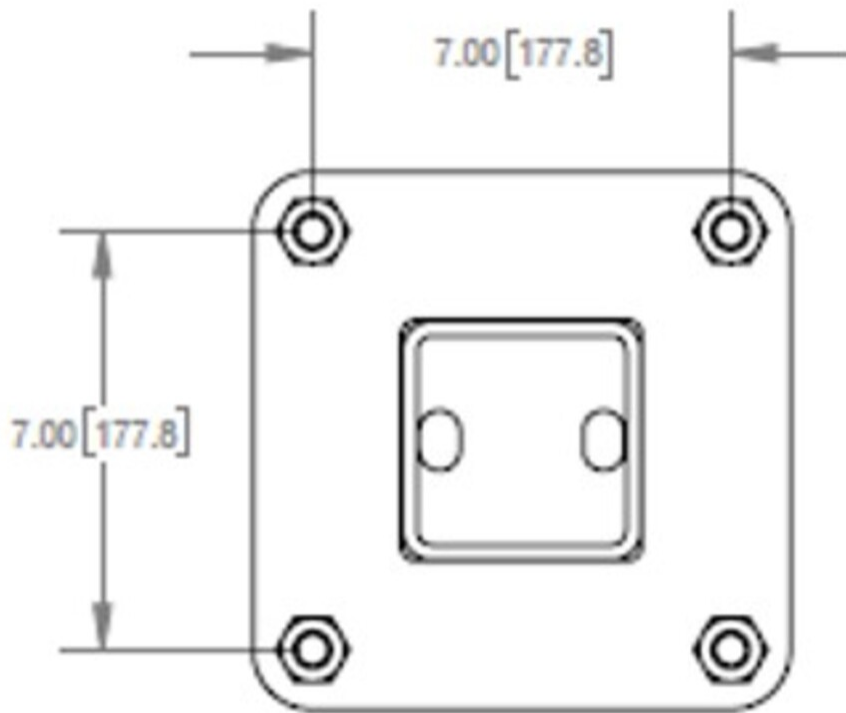

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact steelproducts@commscope.com or call 800-255-1479

Wind Rating Test Method TIA/EIA-222-G

Packaging and Weights

Included Hardware | Stand-off arms | U-bolts

Packaging quantity 1

Weight, net 26.8 kg | 59.084 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value

MC-SA24-B

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code