


MT-F1542-11

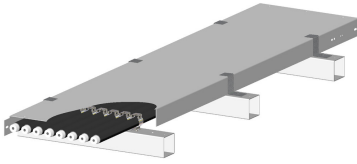

Rooftop Coaxial Cable Bridge Kit, for four coaxial cable runs, 12-gauge cover

Product Classification

Product Type Bridge kit

General Specifications

Cable Runs, quantity 4

Hole, quantity 4

Mounting Non-penetrating

Dimensions

Height 177.8 mm | 7 in

Width 508 mm | 20 in


Length 2,438.4 mm | 96 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Hole Size 3/4 in

MT-F1542-11

Outline Drawing

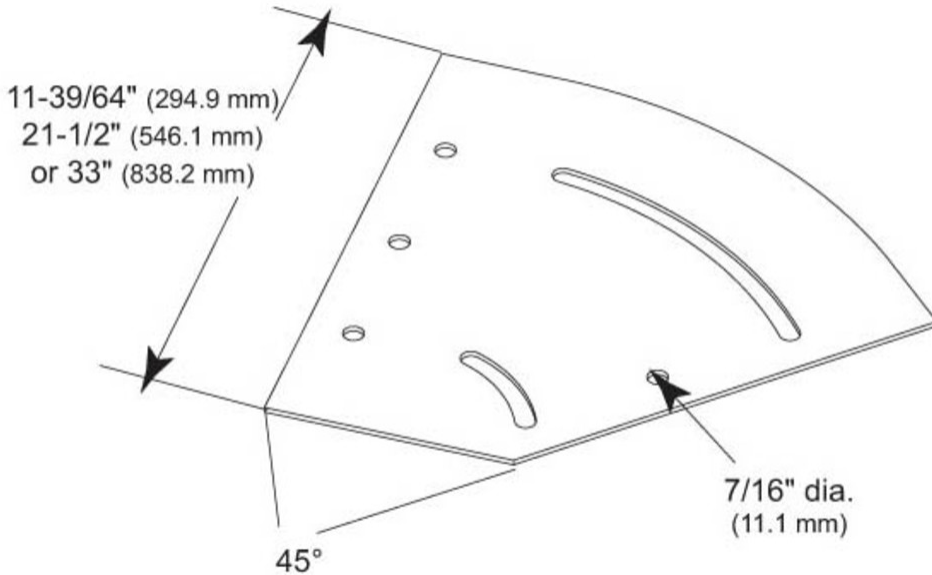

Material Specifications

Material Type Galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact steelproducts@commscope.com or call 800-255-1479

Packaging and Weights

Included Channel | Hardware | Sleepers (3)

Packaging quantity 1

Weight, net 34.8 kg | 76.721 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

MT-F1542-11

UK-ROHS

Compliant



* Footnotes

Wind Rating

BWS—Base Wind Speed; FBC—Florida Building Code