


XA-U

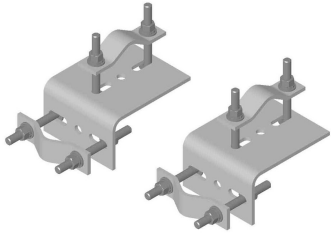

Universal Crossover Angle, 2 in to 3-1/2 in

Product Classification

Product Type Mounting kit

General Specifications

Mounting Pipe, 50.8–88.9 mm (2–3 1/2 in) OD

Tower Taper Non-tapered | Tapered

Dimensions

Height 101.6 mm | 4 in

Length 101.6 mm | 4 in

Mounting Diameter, maximum 88.9 mm | 3.5 in

Mounting Diameter, minimum 50.8 mm | 2 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Angle | Clamps

Packaging quantity 2

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

