


MC-CP12M-B

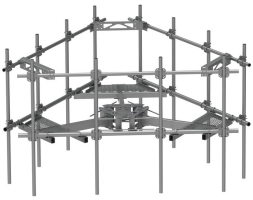

3-Sector Monopole Co-location Platform Base Kit, 12 in to 50 in OD, 12 ft 6 in face, pipe ordered separately

Product Classification

Product Type Co-location platform

General Specifications

Mounting Monopole, 304.8–1270 mm (12–50 in) OD

Pipe, quantity 0

Sectors, quantity 3

Dimensions

Face Width 3.81 m | 12.5 ft

Width 3810 mm | 150 in

Mounting Diameter, maximum 1270 mm | 50 in

Mounting Diameter, minimum 304.8 mm | 12 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating 120 mph (BWS) at 100 ft AGL | 140 mph (3-second gust) at 150 ft AGL using Exposure D per FBC

Wind Rating Test Method TIA/EIA-222

Packaging and Weights

Included Platform | Rail | Ring mount

Packaging quantity 1

MC-CP12M-B

Weight, net 650.678 kg | 1,434.5 lb

* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code