


2160937-1 | OCP-SF-02MASEN-XX-(12COL)

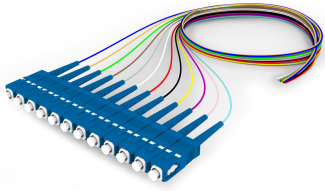

Fiber Optic Pigtail, Simplex, Singlemode, SC/UPC to Stub, 0.9 mm diameter, multicolor, 2 m

Product Classification

Regional Availability	EMEA
Product Type	Fiber pigtail, jacketed
Product Series	OCP


General Specifications

Connector A, quantity	12
Color, boot A	Blue
Color, connector A	Blue
Interface, Connector A	SC/UPC
Total Fibers, quantity	12

Dimensions

Cord Length 2 m | 6.562 ft

Ordering Tree

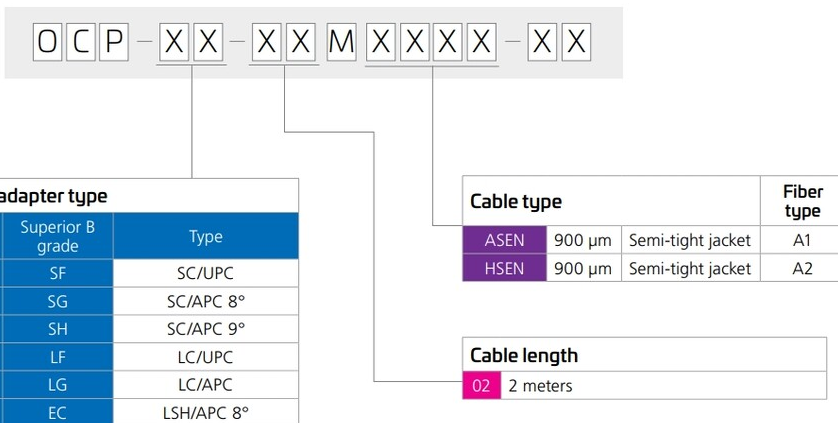

- Standard Configuration by default 900μm buffer
 buffer color : yellow
 250 μm color : natural or milky white

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A1, TeraSPEED®

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

