

RM-SM190-60



Non-Penetrating Roof Mount

Product Classification

Product Type Tripod mount

General Specifications

Mounting Non-penetrating

Pipe, quantity 1

Dimensions

Height 1524 mm | 60 in

Width 914.4 mm | 36 in


Length 0.914 m | 3 ft

Pipe Length 1524 mm | 60 in

Pipe Outer Diameter 48.26 mm | 1.9 in

RM-SM190-60

Outline Drawing

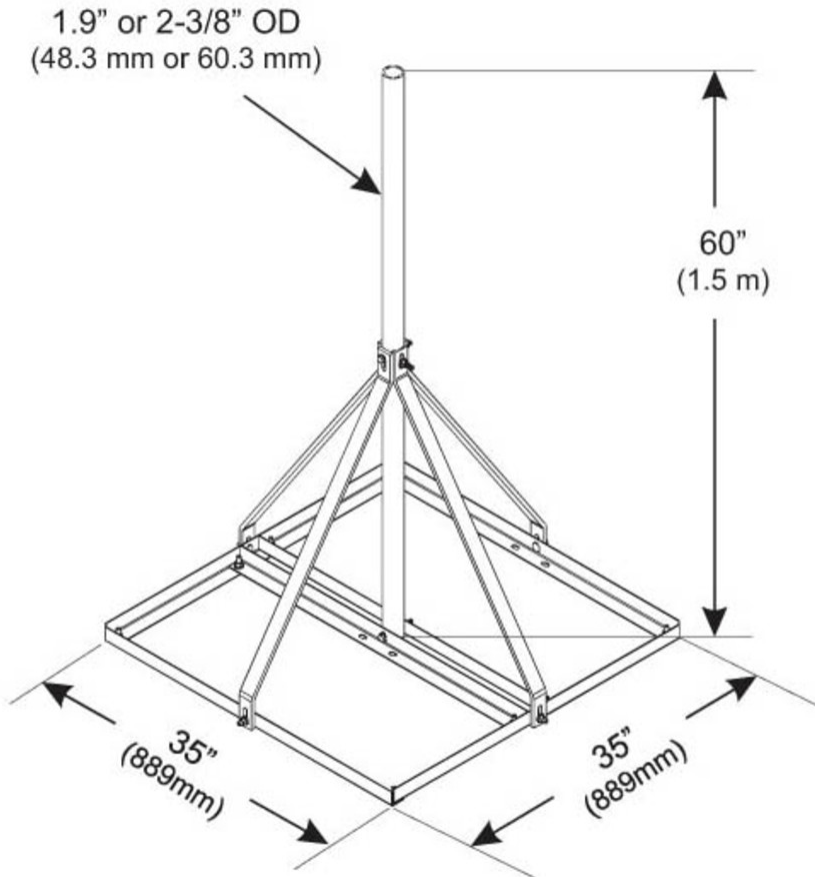

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact steelproducts@commscope.com or call 800-255-1479

Packaging and Weights

Included Ballast tray | Mast | Supports

Packaging quantity 1

Weight, net 27.2 kg | 59.966 lb

RM-SM190-60

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code