


FAXLCUC01

Base Product

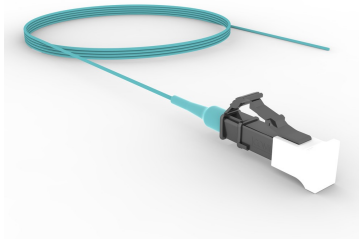

OM4 LC/UPC to Unconnectorized, 0.9mm Tight Buffer Simplex Fiber Pigtail

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	SYSTIMAX InstaPATCH® 360
Product Series	FAX
Ordering Note	Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Aqua
Color, connector A	Black
Interface, Connector A	LC/UPC
Jacket Color	Aqua
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 20
Cable Assembly Length Range (ft)	1 – 66

Ordering Tree

FAXLCUC01

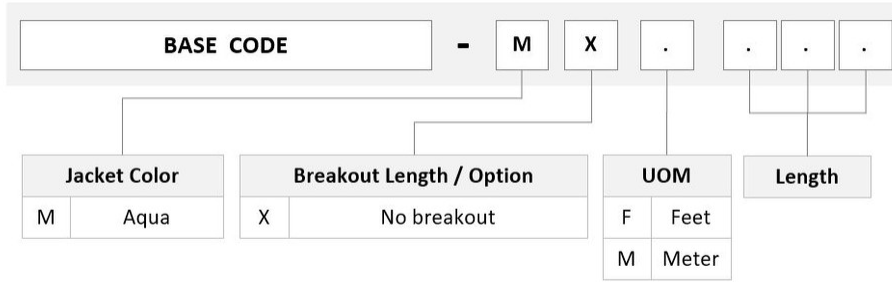

Mechanical Specifications

Cable Retention Strength, maximum 1.00 lb @ 0 ° | 1.00 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Unrated

Packaging and Weights

Packaging quantity 2

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

FAXLCUC01

- 760039347 – LazrSPEED® 900µm Tight Buffered Fiber
X-TB-5K-AQ-F/G
- 860657284 – LC/UPC Connector, Multimode, Aqua