


760241378 | EPX-SPLICE-48 (AGL-SPLICE-48)

Fiber Optic Splice Tray Kit, stackable, 48-fiber capacity

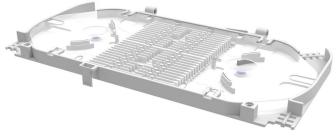

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber splice tray
Product Series	EPX

General Specifications

Application	Used in AGILE panels and enclosures
Color	Light gray
Splicing Capacity, maximum	48

Dimensions

Height	17.6 mm 0.693 in
Width	220 mm 8.661 in
Depth	118.4 mm 4.661 in

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

760241378 | EPX-SPLICE-48 (AGL-SPLICE-48)

UK-ROHS

Compliant

