


760109520 | 360G2 Cartridge 6-SC-LS-AQ-PIGTAILS B

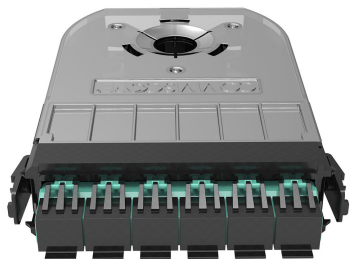

360G2 Multimode OM4 Fiber Cassette 6 SC with pigtails B

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette with pigtails
Product Series	G2

General Specifications

Color, front	Aqua
Intelligence Type	Not iPatch® ready
Interface, front	SC/UPC
Interface, rear	Stranded pigtail
Total Ports, quantity, front	6

Dimensions

Height	25.908 mm 1.02 in
Width	94.996 mm 3.74 in
Depth	123.012 mm 4.843 in

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4
Insertion Loss, maximum	0.33 dB

Environmental Specifications

Qualification Standards	IEC 61753-1 TIA-568.3-D
--------------------------------	---------------------------

760109520 | 360G2 Cartridge 6-SC-LS-AQ-PIGTAILS B

Safety Standard

CE | CSA | UL

Packaging and Weights

Packaging quantity

1

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

