


FE-12104-GC-8-R4

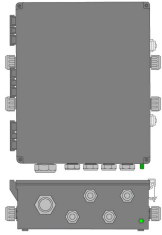

Fiber and Power Junction Box for 1 808 Series Hybrid Trunk / 4 Hybrid Jumper Cables / 4 Power Ports with Internal Grounding / 4 Conduit fittings

Product Classification

Regional Availability

Asia | Australia/New Zealand | EMEA | Latin America | North America

Portfolio

CommScope®

Product Type

Outdoor junction box

General Specifications

Application

Used as a fiber/power junction box

Cable Entry, quantity, maximum, bottom

5

Cable Entry, quantity, maximum, left

4

Color

Gray

Mounting

Pipe, 44–114 mm (1.75–4.5 in) OD | Wall

Dimensions

Height

317.5 mm | 12.5 in

Width

266.7 mm | 10.5 in

Depth

101.6 mm | 4 in

Cable Entry Fiber Gland Size, maximum

32 mm | 1.26 in

Cable Entry Fiber Gland Size, minimum

22 mm | 0.866 in

Cable Entry Jumper Gland Size, maximum

18 mm | 0.709 in

Cable Entry Jumper Gland Size, minimum

13 mm | 0.512 in

Material Specifications

Material Type

High-impact polycarbonate, UV resistant

Environmental Specifications

Operating Temperature

-40 °C to +75 °C (-40 °F to +167 °F)

Environmental Space

Indoor | Outdoor

FE-12104-GC-8-R4

Qualification Standards IEC 60529:2001, IP67

Packaging and Weights

Included Mounting kit

Weight, net 1.579 kg | 3.48 lb

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system