

860651965 | Round Straight 8.625" with multiple Lum mounts



8.625" diameter pole that accomodates Small Cell equipment and Smart City devices with alternative luminaire mounting elevations

Metal pole that supports a variety of installation methods such as poured concrete, embedded pole, pre-cast, and helical foundations
Break Away Compatible
Configurable color and pole height

Foundation Kit Ordered Separately

Product Classification

Portfolio	CommScope®
Product Type	Standard poles
Product Brand	Metro Cell
Ordering Note	CommScope® standard product with terms
Warranty	One year

General Specifications


Color	Galvanized
Color Options	Antique Bronze (SRSL 45893) Beige-Grey (RAL 7006) Black (RAL 9005) Black Green (RAL 6012) Brown (RAL 8014) Fairfax Brown (SW 2856) Faux Concrete Federal Park Brown Green (RAL 6005) Light Gray (RAL 7035) Metallic Silver Signal Black (RAL 9004) Umbra Grey (RAL 7022) White (RAL 9010)
Compatible Foundation Type	Embedded Pole Embedded with Foam Helical Anchor Poured Concrete Pre-Cast Concrete Split Helical Anchors
Compatible Smart Devices	Cameras Digital Signage Emergency Call Station Environmental Monitoring Security Lighting WIFI

Dimensions

Pole Height Options	9.144 m 30 ft 9.754 m 32 ft
Width	219.075 mm 8.625 in
Luminaire Mount Height	8.23 m 27 ft 8.931 m 29.3 ft 9.54 m 31.3 ft
Mounting Bolt Circle Diameter	406.4 mm 16 in

860651965 | Round Straight 8.625" with multiple Lum mounts

Ordering Tree

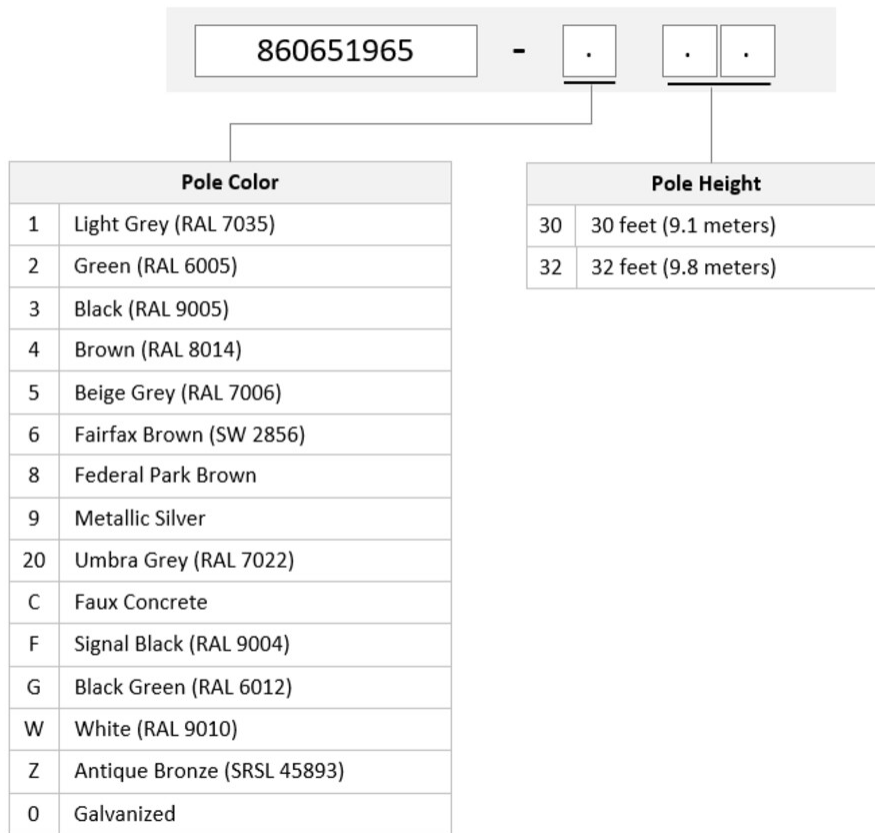

Material Specifications

Finish	Powder coated
Material Type	Galvanized steel

* Footnotes

Warranty	For more information, please consult our Product Warranty guidelines
Pole Height Options	Overall AGL Standard Height