


9-552041-3 | INLINE MINI, BLUE, STRIP

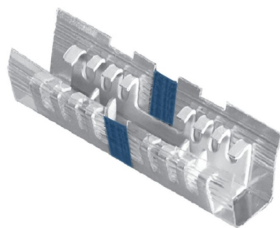

Inline connector, 1000 strip, mini, blue

- Lightweight, compact, and economical means of splicing multiconductor telephone cable
- No prestripping or cutting required, can tap without service interruptions, eliminates “turndowns”
- Color-coded to indicate size and type of wire; used for high count straight splicing applications

Product Classification

Regional Availability	Australia/New Zealand China EMEA Latin America North America
Product Type	Splice

General Specifications

Connector Color Code	Blue
Connector Sealant	Unfilled
Connector Splicing Type	High Count Straight

Dimensions

Compatible Conductor Gauge, solid	26–22 AWG
--	-----------

Electrical Specifications

Dielectric Strength	1 kV
Safety Voltage Rating	400 Vdc

Material Specifications

Contact Base Material	Phosphor Bronze
Contact Plating Material	Tin
Insulation Material	Air Core PIC Paper or Pulp

Environmental Specifications

Operating Temperature	-40 °C to +60 °C (-40 °F to +140 °F)
Environmental Space	Outdoor

Packaging and Weights

9-552041-3 | INLINE MINI, BLUE, STRIP

Packaging quantity 1000

Packaging Type Strip

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

