


MT-180

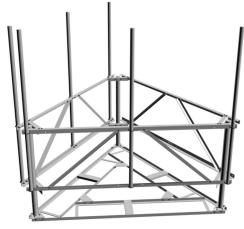

Multi-Sector Roof Frame Only, 10 ft face, Non-Penetrating Sled (MT-181) and pipe sold separately

Product Classification

Product Type Rooftop sector frame

General Specifications

Mounting Non-penetrating

Dimensions

Height 3,124.2 mm | 123 in

Face Width 3.048 m | 10 ft

Width 3,124.2 mm | 123 in

Length 1.524 m | 5 ft

Pipe Outer Diameter 60.96 mm | 2.4 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact steelproducts@commscope.com or call 800-255-1479

Packaging and Weights

Included Mount | U-bolts

Packaging quantity 1

Weight, net 211.2 kg | 465.616 lb

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

MT-180

* Footnotes

Wind Rating

BWS—Base Wind Speed; FBC—Florida Building Code