


# HS-400

---

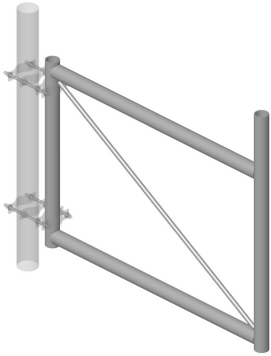

Stand-Off Bracket, heavy duty, 48 in, includes pipe

## Product Classification

**Product Type** Stand-off mount

## General Specifications

**Note** One 72 in x 8 in panel antenna per sector

**Pipe, quantity** 1

## Dimensions

**Height** 1,066.8 mm | 42 in

**Width** 76.2 mm | 3 in

**Length** 1,219.2 mm | 48 in


**Pipe Length** 1,066.8 mm | 42 in

**Pipe Outer Diameter** 60.96 mm | 2.4 in

**Stand-off Distance** 1,219.2 mm | 48 in

# HS-400

## Outline Drawing

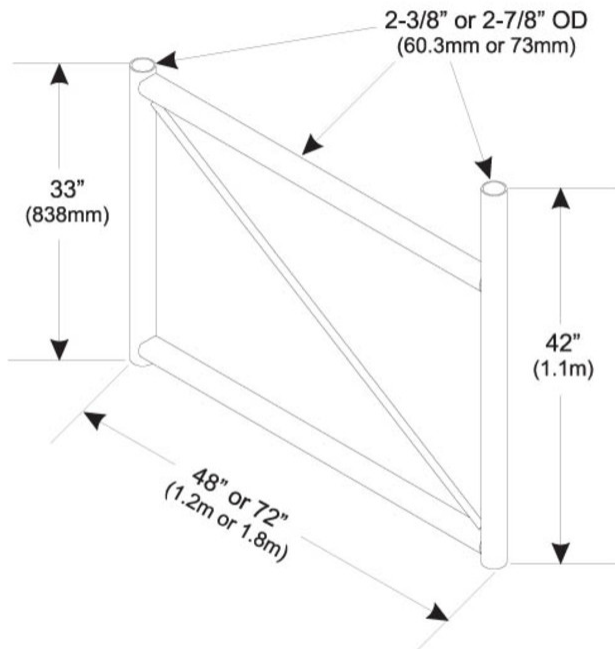

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** 120 mph (BWS) at 150 ft AGL

**Wind Rating Test Method** TIA/EIA-222

## Packaging and Weights

**Included** Stand-off

**Packaging quantity** 1

# HS-400

---

**Weight, net**

25.3 kg | 55.777 lb

## Regulatory Compliance/Certifications

**Agency****Classification**

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant



## \* Footnotes

**Wind Rating**

BWS—Base Wind Speed; FBC—Florida Building Code