

RAPID-FIBER-PANELS



Rapid Fiber Panels are available with SC or LC connectors on the front, singlemode or multimode, and Indoor/Outdoor or Plenum cable with single fiber breakouts (SC or LC), MPO's or stub on the far-end.

Rapid Fiber Panels utilize CommScope's unique RapidReel fiber cable spools so the cable is always the right length. Available to store up to 100' of cable inside the panel up to 1000' of total cable length.

The Rapid Fiber panel offers service providers unmatched savings in installation time, labor costs and performance.

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel, with rapid cable
Product Brand	RapidFiber®
Product Series	RCP

General Specifications


Functionality	Patching
Rack Type	EIA 19 in EIA 23 in

Dimensions

Width	482.6 mm 19 in
Depth	381 mm 15 in

Ordering Tree

RAPID-FIBER-PANELS

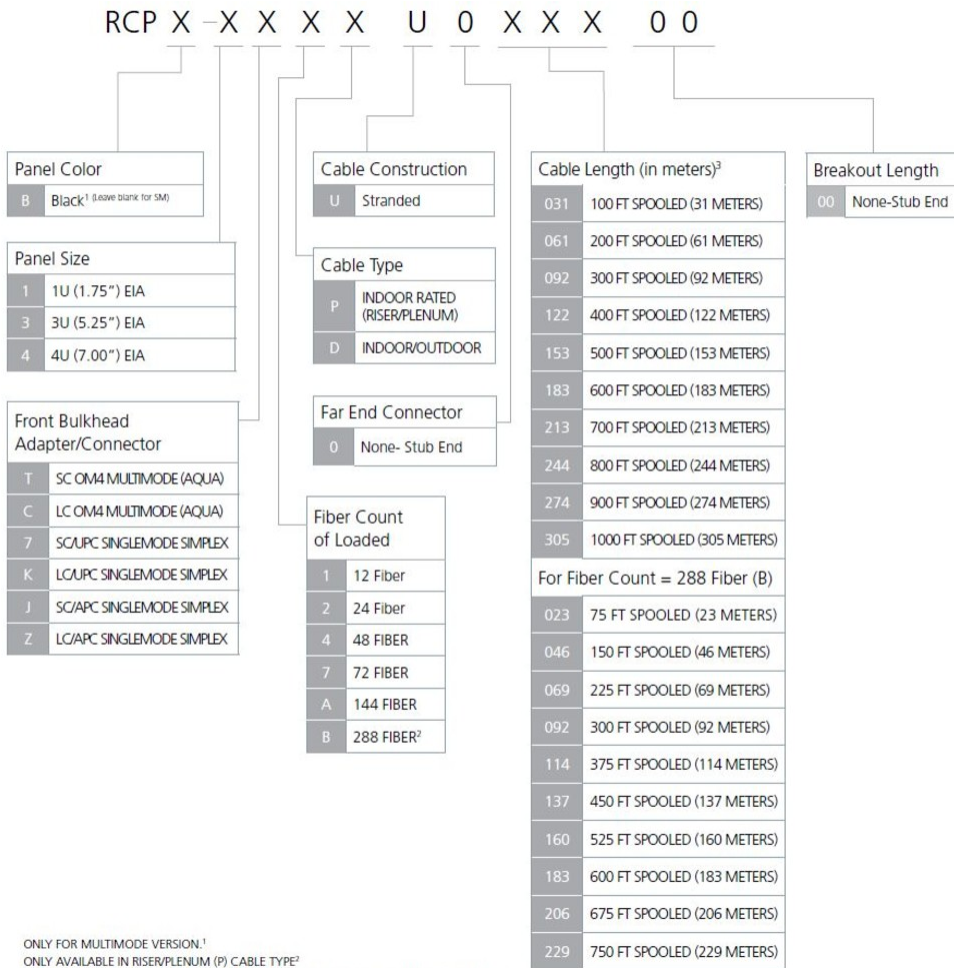

Environmental Specifications

Qualification Standards

NEBS Level 3 | Telcordia GR-1435 | Telcordia GR-326 | Telcordia GR-409 | UL 1863