


FDC-AT-S28-02018

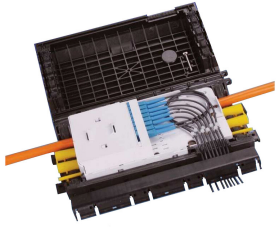

FDC Fiber Optic Splice/Patch Closure, Gel Cable Sealing, 8 SC/APC Adapters, 24 fusion splices

Product Classification

Regional Availability	Asia EMEA Latin America
Product Type	In-line, rectangular fiber closure
Product Series	FDC

General Specifications

Cable Ports Quantity, total	6 round ports
Cable Sealing Type	Compressed gel
Closure Sealing Type	Hinged with latch
Closure Style	In-line
Color	Black
Mounting	Manhole Pedestal Strand Wall
Port Type	SC/APC
Port, quantity	8
Splice Tray Included, quantity	1
Splice Tray Type Included	24-way, heat shrink
Splitter Type	No splitter
Splitter, quantity	0

Dimensions

Height	83 mm 3.268 in
Width	160 mm 6.299 in
Length	270 mm 10.63 in

Material Specifications

Material Type	Rugged polymer
----------------------	----------------

FDC-AT-S28-02018

Environmental Specifications

Environmental Space Above ground | Below ground

Packaging and Weights

Included Splitter (1)

Packaging quantity 1

Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

