


# RCP-171DUE15300

---

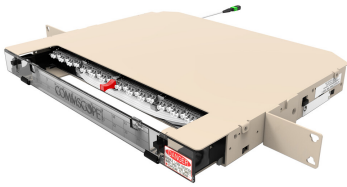

RapidFiber® Termination Panel, 12-Position 1RU, singlemode, SC/UPC to MPO, 53 m

## Product Classification

|                              |                                     |
|------------------------------|-------------------------------------|
| <b>Regional Availability</b> | Latin America   North America       |
| <b>Portfolio</b>             | CommScope®                          |
| <b>Product Type</b>          | Fiber patch panel, with rapid cable |
| <b>Product Brand</b>         | RapidFiber®                         |
| <b>Product Series</b>        | RCP                                 |

## General Specifications

|                                  |                                               |
|----------------------------------|-----------------------------------------------|
| <b>Functionality</b>             | Patching                                      |
| <b>Body Style</b>                | Symmetrical                                   |
| <b>Cable Exit Location</b>       | Rear, left side                               |
| <b>Cable Stub Type</b>           | Indoor/outdoor, microcable                    |
| <b>Color</b>                     | Putty white                                   |
| <b>Door Type, front</b>          | Hinged   Slide latch   Transparent            |
| <b>Growth Configuration</b>      | Fully loaded                                  |
| <b>Interface, front</b>          | SC/UPC                                        |
| <b>Interface, rear</b>           | MPO                                           |
| <b>Patch Cord Entry Location</b> | Front, left side   Front, right side          |
| <b>Rack Type</b>                 | EIA 19 in   EIA 23 in                         |
| <b>Rack Units</b>                | 1                                             |
| <b>Shelf Movement</b>            | Sliding                                       |
| <b>Total Fibers, quantity</b>    | 12                                            |
| <b>Total Ports, quantity</b>     | 12                                            |
| <b>Transmission Standards</b>    | IEC 60794-2   ISO/IEC 11801   TIA/EIA-568-B.3 |


## Dimensions

|               |                    |
|---------------|--------------------|
| <b>Height</b> | 44.45 mm   1.75 in |
| <b>Width</b>  | 482.6 mm   19 in   |

# RCP-171DUE15300

**Depth** 381 mm | 15 in  
**Cable Length** 53 m | 173.885 ft

## Ordering Tree

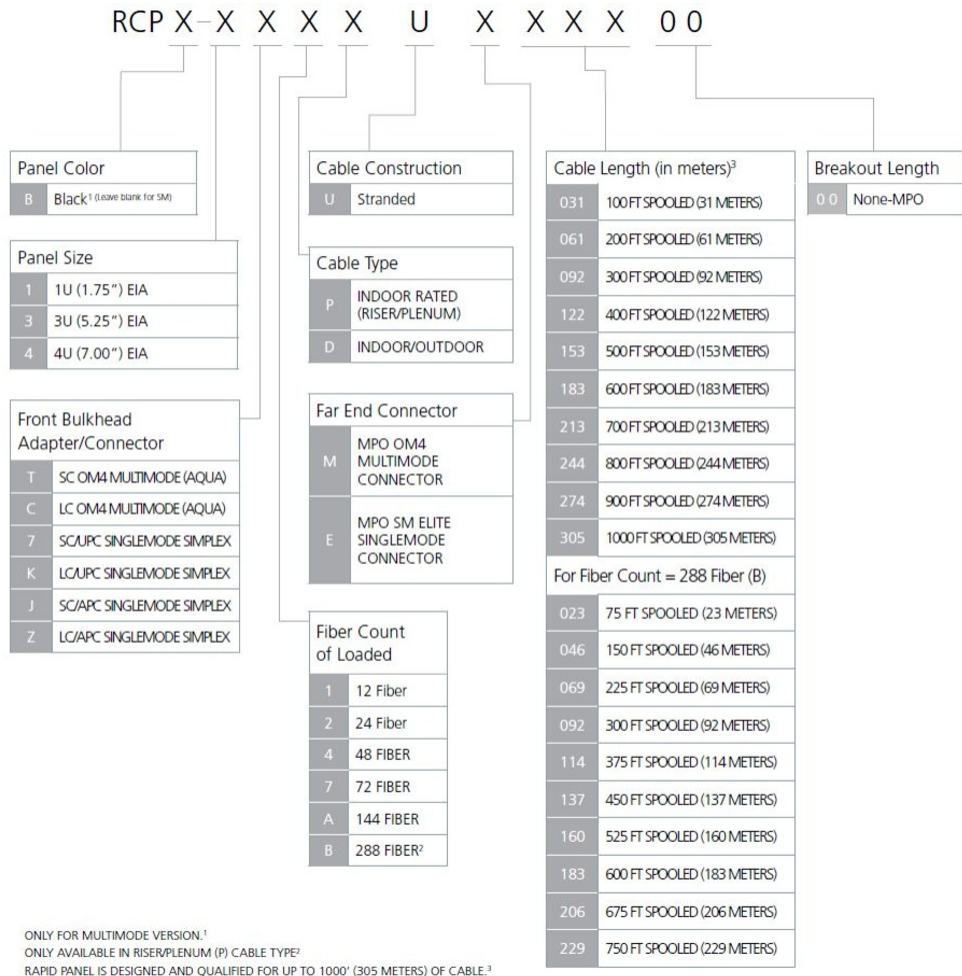

## Material Specifications

**Finish** Powder coated  
**Material Type** Steel

## Optical Specifications

**Fiber Mode** Singlemode  
**Fiber Type** G.652.D | G.657.A2/B2

# RCP-171DUE15300

---

## Environmental Specifications

|                                |                                                                                  |
|--------------------------------|----------------------------------------------------------------------------------|
| <b>Operating Temperature</b>   | -5 °C to +55 °C (+23 °F to +131 °F)                                              |
| <b>Storage Temperature</b>     | -40 °C to +70 °C (-40 °F to +158 °F)                                             |
| <b>Relative Humidity</b>       | 5%–85%, non-condensing                                                           |
| <b>Qualification Standards</b> | NEBS Level 3   Telcordia GR-1435   Telcordia GR-326   Telcordia GR-409   UL 1863 |

## Packaging and Weights

|                           |   |
|---------------------------|---|
| <b>Packaging quantity</b> | 1 |
|---------------------------|---|