


760109256 | 360G2 Cartridge 12-LC-LS-AQ

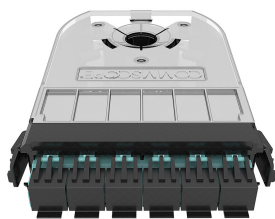

360G2 Multimode OM4 Fiber Cassette 12 LC no pigtails, iPatch Ready

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette
Product Series	G2

General Specifications

Color, front	Aqua
Intelligence Type	iPatch® ready
Interface, front	LC/UPC
Interface, rear	No pigtail
Shuttered	No
Total Ports, quantity, front	12

Dimensions

Height	25.908 mm 1.02 in
Width	94.996 mm 3.74 in
Depth	123.012 mm 4.843 in

Optical Specifications

Fiber Mode	Multimode
-------------------	-----------

Environmental Specifications

Qualification Standards	IEC 61753-1 TIA-568.3-D
Safety Standard	CE CSA UL

Packaging and Weights

Packaging quantity	1
---------------------------	---

760109256 | 360G2 Cartridge 12-LC-LS-AQ

Weight, net

0.071 kg | 0.157 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

