


# FAWLAUC01

---

## Base Product

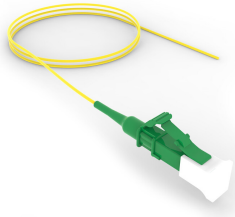

TeraSPEED® LC APC to Unconnectorized, Fiber Pigtail, 0.9 mm Tight Buffer

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber pigtail, unjacketed  |
| <b>Product Brand</b>         | SYSTIMAX InstaPATCH® 360   |
| <b>Product Series</b>        | FAW  |
| <b>Ordering Note</b>         | Minimum length may vary based on cable configuration   |

## General Specifications


|                               |        |
|-------------------------------|--------|
| <b>Color, boot A</b>          | Green  |
| <b>Color, connector A</b>     | Green  |
| <b>Interface, Connector A</b> | LC/APC |
| <b>Jacket Color</b>           | Yellow |
| <b>Total Fibers, quantity</b> | 1      |

## Dimensions

|   |        |
|---|--------|
| <b>Cable Assembly Length Range (m)</b>  | 1 – 20 |
| <b>Cable Assembly Length Range (ft)</b> | 1 – 66 |

## Ordering Tree

# FAWLAUC01

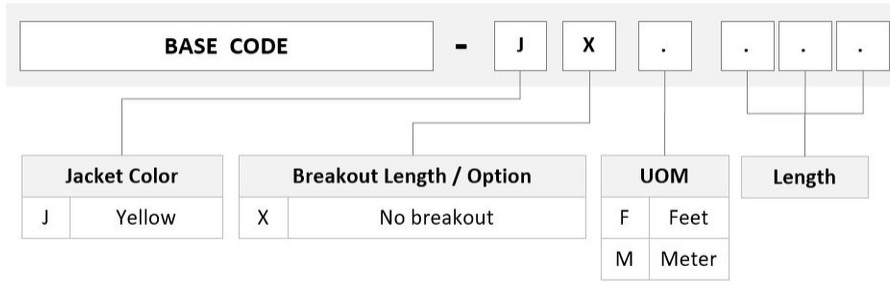

## Mechanical Specifications

**Cable Retention Strength, maximum** 1.00 lb @ 0 ° | 1.00 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.652.D | G.657.A1, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Unrated

## Packaging and Weights

**Packaging quantity** 2

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |



## Included Products

760038570 – TeraSPEED® 900µm Tight Buffered Fiber  
X-TB-8W-YL-F/G

# FAWLAUC01

---

860637438 - LC/APC Connector, Singlemode, Green