



LightCrimp Plus™ Fiber Optic Termination Tool Kit, LC/SC, with microscope

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber tool kit
<b>Product Brand</b>	LightCrimp Plus™
<b>Product Series</b>	LightCrimp

## General Specifications

<b>Interface</b>	LC   SC
------------------	---------

## Environmental Specifications

<b>Environmental Space</b>	Indoor
----------------------------	--------

## Packaging and Weights

<b>Included</b>	200X Microscope kit with 2.5mm adapter cap   Alcohol fiber wipes   Ball and hex key   Carrying case   Fiber cleaver   Instruction sheet   Kevlar cutter   LC+ LC/SC cable holder   Miller dual-hole strip tool   Pro-crimper, LC+ LC/SC/Splice   Slitter tool, 2 mm and 3 mm   Stripper, micro-strip W/.008BLA   Universal 1.25mm microscope adapter   Wrench, open end ¼
<b>Packaging quantity</b>	1

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

- 1754765-1 – Fiber Optic Universal 1.25 mm Adapter for Hand-held Inspection Microscope
- 1754767-1 – Fiber Optic Hand-held Inspection Microscope
- 760243578 – Fiber Optic Hand Held Precision Cleaver Tool

# 1754765-1

---



## Fiber Optic Universal 1.25 mm Adapter for Hand-held Inspection Microscope

### Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber inspection microscope adapter

### General Specifications

<b>Color</b>	Black
--------------	-------

### Environmental Specifications

<b>Environmental Space</b>	Indoor
----------------------------	--------

### Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

### Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant





## Fiber Optic Hand-held Inspection Microscope

- High quality glass optics with 200x magnification and an impact resistant ergonomic rubber shell
- Dual illumination lighting and IR-Laser attenuation filter and 500um Field of View (FOV)
- Protected by a padded carrying case with an integrated belt loop and internal adapter storage pocket

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber inspection microscope

## General Specifications

**Color** Black

## Dimensions

<b>Height</b>	31.5 mm   1.24 in
<b>Width</b>	51.6 mm   2.031 in
<b>Length</b>	186.9 mm   7.358 in

## Environmental Specifications

**Environmental Space** Indoor

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Weight, net</b>	0.318 kg   0.7 lb


## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

1754767-1

---



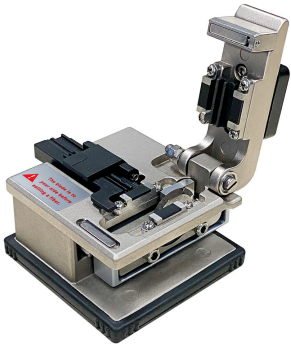

## Fiber Optic Hand Held Precision Cleaver Tool

- Provides operator-independent precision quality cleaves in a hand held size
- Includes a blade knife with a 48,000 cleave lifetime
- Suited for field installable mechanical splice connectors, bare fiber adapters and fusion and mechanical splicing
- Supplied with a padded belt case with neck lanyard for convenience and storage

## Product Classification

<b>Regional Availability</b>	Asia   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber tool kit

## Dimensions

<b>Height</b>	46 mm   1.811 in
<b>Width</b>	53 mm   2.087 in
<b>Length</b>	55 mm   2.165 in

## Environmental Specifications

<b>Environmental Space</b>	Indoor
----------------------------	--------

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Weight, net</b>	500 g   1.102 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

