


FE-12106-R11

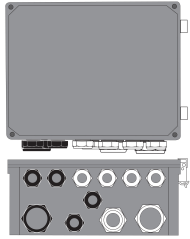

HELIAX® Fiber and Power Junction Box for 1 Hybrid Trunk, 1 Fiber Trunk, 1 Power Trunk, 8 Hybrid Jumper, Grey Terminal Blocks, 2 Grounding Blocks

Product Classification

Regional Availability

Asia | Australia/New Zealand | EMEA | Europe | Latin America | North America

Portfolio

CommScope®

Product Type

Outdoor junction box

Product Brand

HELIAX®

General Specifications

Application

Used as a fiber/power junction box

Cable Entry, quantity, maximum, bottom

11

Color

Gray

Mounting

Pipe, 44–114 mm (1.75–4.5 in) OD | Wall

Dimensions

Height

317.5 mm | 12.5 in

Width

266.7 mm | 10.5 in

Depth

152.4 mm | 6 in

Material Specifications

Material Type

High-impact polycarbonate, UV resistant

Environmental Specifications

Operating Temperature

-40 °C to +75 °C (-40 °F to +167 °F)

Environmental Space

Indoor | Outdoor

Qualification Standards

IEC 60529:2001, IP67

Packaging and Weights

Included

Mounting kit

FE-12106-R11

Weight, net

2.268 kg | 5 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

