


MF-126

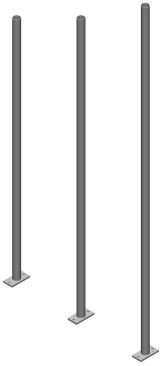

Base Shoe Pipe Column, 10 ft 6 in

Product Classification

Product Type Pipe column

General Specifications


Application Base shoe
Mounting Waveguide bridge support bracket
Pipe, quantity 1

Dimensions

Height 3,200.4 mm | 126 in
Width 127 mm | 5 in
Length 254 mm | 10 in
Pipe Length 3,200.4 mm | 126 in
Pipe Outer Diameter 88.9 mm | 3.5 in

MF-126

Outline Drawing

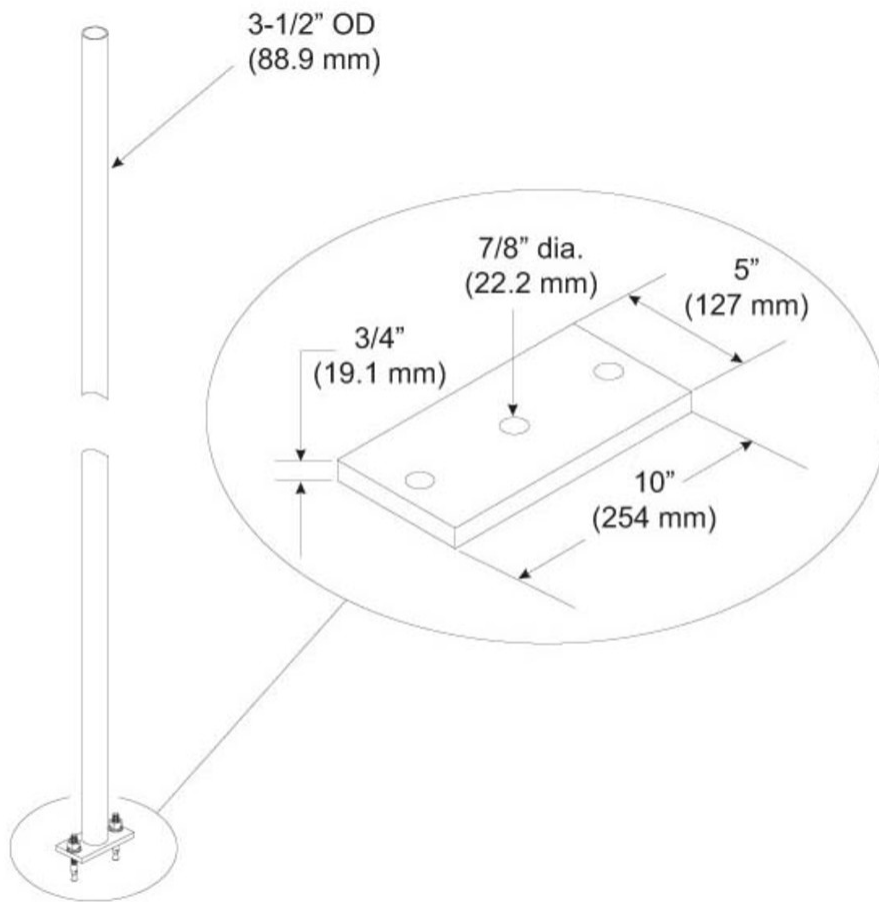

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Anchors | Pipe

Packaging quantity 1

Weight, net 41.7 kg | 91.933 lb

Regulatory Compliance/Certifications

Agency **Classification**

MF-126

CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

 


Included Products

MT-287 – Wedge Anchor, 3/4 in x 7 in

MT-287

Wedge Anchor, 3/4 in x 7 in



Product Classification

Product Type Anchor

Dimensions

Height 25.4 mm | 1 in

Width 25.4 mm | 1 in

Length 177.8 mm | 7 in

Pipe Outer Diameter 20.32 mm | 0.8 in

Material Specifications

Material Type Plated steel

Packaging and Weights

Included Anchors

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system