


CAF-6C6C-LSON

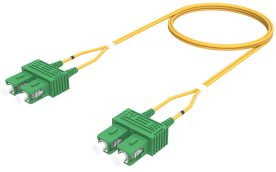

Armored Jumper G657.A2 SC/APC to SC/APC Duplex, 3.0mm LSZH, Yellow

Product Classification

Regional Availability	Asia Australia/New Zealand China India
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex

General Specifications

Connector A, quantity	2
Color, boot A	Green
Color, connector A	Green
Connector B, quantity	2
Color, boot B	Green
Color, connector B	Green
Construction Type	Armored
Interface, Connector A	SC/APC
Interface, Connector B	SC/APC
Jacket Color	Yellow
Polarity	Pairs, flipped
Total Fibers, quantity	2

Dimensions

Cable Assembly Length Range (m)	1 – 300
Cable Assembly Length Range (ft)	3 – 999
Diameter Over Jacket	3 mm 0.118 in

Mechanical Specifications

Tensile Load, long term, maximum	200 N 44.962 lbf
Tensile Load, short term, maximum	400 N 89.924 lbf

CAF-6C6C-LSON

Cable Retention Strength, maximum 15.43 lb @ 0°

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A2, TeraSPEED®
Insertion Loss, maximum 0.25 dB
Return Loss, minimum 60 dB

Environmental Specifications

Operating Temperature -25 °C to +70 °C (-13 °F to +158 °F)
Environmental Space Low Smoke Zero Halogen (LSZH)
Qualification Standards IEC 61753-1, category OP

Packaging and Weights

Packaging quantity 1