


MQGQW2QW28R

Base Product

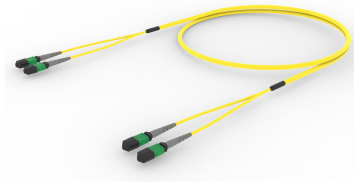

Ultra Low Loss (ULL) SingleMode 2xMPO8 Non-Pinned with Push-Pull Boot to 2xMPO8 Non-Pinned with Push-Pull Boot, Mesh Array, 16-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	2
Color, boot A	Black
Color, connector A	Yellow
Connector B, quantity	2
Color, boot B	Black
Color, connector B	Yellow
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Female
Interface Body Style, connector A	Push-pull boot
Interface, Connector B	MPO-08/APC Female
Interface Body Style, connector B	Push-pull boot
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	16

MQGQW2QW28R

Dimensions

Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Representative Image

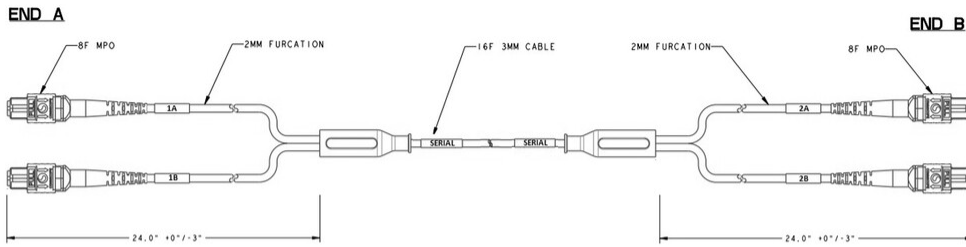

FIBER ROUTING			
END A		END B	
MPO 8 1A	MPO 8 1B	MPO 8 2A	MPO 8 2B
1		12	
2		11	
3			12
4			11
9			2
10			1
11		2	
12		1	
	1	10	
	2	9	
	3		10
	4		9
	9		4
	10		3
	11	4	
	12	3	

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	0 °C to +60 °C (+32 °F to +140 °F)
Environmental Space	Indoor Plenum

Regulatory Compliance/Certifications

Agency	Classification
---------------	-----------------------

MQGQW2QW28R

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

Included Products

- 460202380 – MPO8/12 ULL Female, Singlemode, Yellow, Push-Pull, 3mm
- 760249691 – Fiber indoor cable, Plenum MPO Light Duty for Patchcords, 16 fiber, Singlemode G.657.A2/B2,
P-016-MP-8G1-F30YL Feet jacket marking, Yellow jacket color