


# UKGQXQXTS

## Base Product

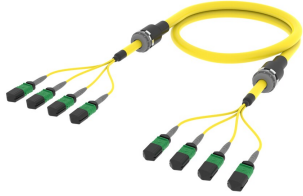

Singlemode MPO8 APC (pinned) to MPO8 APC (pinned) Fiber Trunk Cable Assembly, 32-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	4
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	4
<b>Color, boot B</b>	Gray
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Armored   Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-08/APC Male
<b>Interface, Connector B</b>	MPO-08/APC Male
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	32

## Dimensions

<b>Breakout Length</b>	22 in
------------------------	-------



# UKGQXQXTS

---

UK-ROHS

Compliant/Exempted



## Included Products

- 760255999  
N-032-MZ-8G1-F08YL/20T/B2 - Fiber indoor cable, Riser/LSZH rated MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2/B2, 32 fiber, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860659022 - MPO-08, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm