

UKGQXUCT8

Base Product



Singlemode MPO8 APC (pinned) to Unconnectorized Fiber Trunk Cable Assembly, 8-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

Propel | SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity

1

Color, boot A

Gray

Color, connector A

Green

Connector B, quantity

0

Construction Type

Armored | Stranded

Furcation Color

Yellow

Interface, Connector A

MPO-08/APC Male

Interface, Connector B

Unterminated

Jacket Color

Yellow

Polarity

Method B Enhanced (ULL)

Fibers per Subunit, quantity

8

Total Fibers, quantity

8

Dimensions

Breakout Length

22 in

Cable Assembly Length Range (m)


3 – 305

Cable Assembly Length Range (ft)

10 – 999

UKGQXUCT8

Ordering Tree

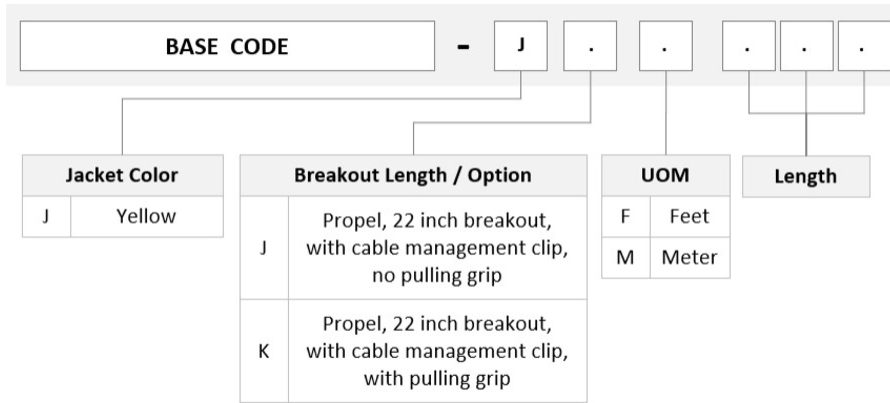

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance Dca

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

UKGQXUCT8



Included Products

- 760255996
N-008-MZ-8G1-F08YL/20T/B2
 - 860659022
- Fiber indoor cable, Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2/B2, 8 fiber, Feet jacket marking, Yellow jacket color, B2ca flame rating
 - MPO-08, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm