

FSXLCLCWL

Base Product

LazrSPEED® 550 LC/UPC to LC/UPC, Distribution Cable, 96-Fiber, Plenum

Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Fiber distribution cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters

General Specifications


Cable Glands	No glands
Color, connector A	Black
Color, connector B	Black
Construction Type	Distribution, indoor
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Total Fibers, quantity	96

Dimensions

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

FSXLCLCWL

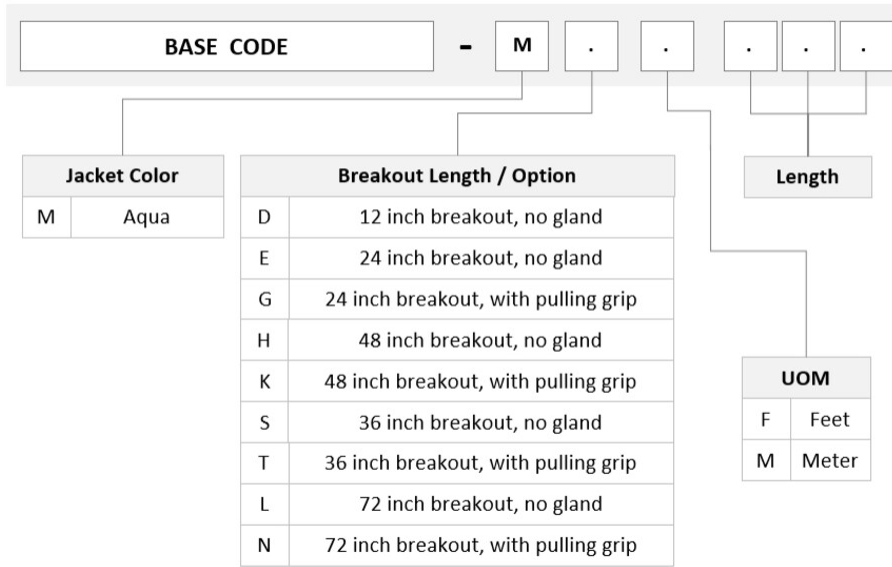

Mechanical Specifications

Cable Retention Strength, maximum 0.50 lb @ 0° | 0.50 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature 0 °C to +70 °C (+32 °F to +158 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



FSXLCLCWL

Included Products

- 460125271 – Behind The Wall Pre-Radiused LC Connector for 0.9 mm Fiber, multimode
- 760021691 – Fiber indoor cable, LazrSPEED® Plenum Distribution, 96 fiber multi-unit with 12 fiber subunits, P-096-DS-5K-FMUAQ Multimode OM4, Feet jacket marking, Aqua jacket color