


# SFG22HDX-11-3-120

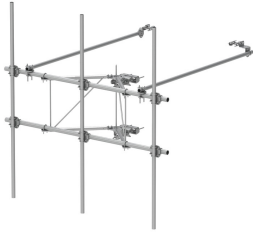

G22HDX Tower Sector Frame with extended face, 11 ft x 2.88 in OD face pipes. Base Kit Only. Includes three 2.88 OD x 120 in antenna pipes

## Product Classification

<b>Product Type</b>	High capacity Tower sector frame
<b>Product Brand</b>	PIM-guard
<b>Product Series</b>	G2

## General Specifications

<b>Mounting</b>	Angle 60°, 203.2 mm (8 in)   Straight or tapered legs up to 203.2 mm (8 in) OD
<b>Pipe, quantity</b>	3
<b>Sectors, quantity</b>	1
<b>Tower Taper</b>	Non-tapered   Tapered

## Dimensions

<b>Face Width</b>	3.353 m   11 ft
<b>Width</b>	3,352.8 mm   132 in
<b>Face Support Pipe Diameter</b>	73.025 mm   2.875 in
<b>Mounting Diameter, maximum</b>	218.44 mm   8.6 in
<b>Mounting Diameter, minimum</b>	38.1 mm   1.5 in
<b>Pipe Outer Diameter</b>	73.025 mm   2.875 in
<b>Stand-off Distance</b>	1,066.8 mm   42 in

## Material Specifications

<b>Material Type</b>	Hot dip galvanized steel
----------------------	--------------------------

## Mechanical Specifications

<b>Wind Rating</b>	For Specifications, please contact <a href="mailto:steelproducts@commscope.com">steelproducts@commscope.com</a> or call 800-255-1479
--------------------	--

## Packaging and Weights

<b>Included</b>	Frame   Plain end pipes (3)   Stiff arms (2)   Tower attachment
-----------------	---

# SFG22HDX-11-3-120

---

**Packaging quantity** 1  
**Weight, net** 284.566 kg | 627.36 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## \* Footnotes

**Wind Rating** BWS—Base Wind Speed; FBC—Florida Building Code