


# NVX-SF-TRAY-S45

---

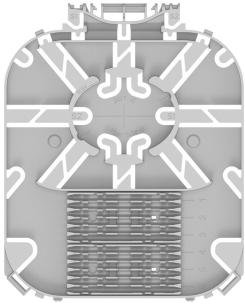

NOVUX™ CSC150 SF tray for 24x SMOUV45 splice protector, kit of 10 pieces

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Product Type</b>	Fiber splice tray kit
<b>Product Brand</b>	NOVUX™
<b>Product Series</b>	NVX
<b>Minimum Order Quantity</b>	1

## General Specifications

<b>Color</b>	Light Gray (RAL 7035)
--------------	-----------------------

## Material Specifications

<b>Material Type</b>	Hardened plastic
----------------------	------------------

## Environmental Specifications

<b>Operating Temperature</b>	-40 °C to +70 °C (-40 °F to +158 °F)
<b>Environmental Space</b>	Above ground   Below ground
<b>Qualification Standards</b>	IEC 60529, IP68 + 2 m waterhead   IEC 61753-1, category G
<b>UV Resistance</b>	UV stabilized

## Packaging and Weights

<b>Packaging quantity</b>	10
<b>Packaging Type</b>	Box

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
---------------	-----------------------

# NVX-SF-TRAY-S45

---

CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

