

FMT-JN2A80460-A24P



FMT Fiber Termination Panel, 24 LC/UPC, singlemode, 1RU, 19 in, putty white, pre-terminated with IFC cable, 46 meters, stub tail at far end

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel, with IFC cable
Product Series	FMT

General Specifications


Functionality	Patching
Body Style	Symmetrical
Cable Stub Type	IFC
Color	Black
Color, front	Putty white
Interface, front	LC
Interface Feature, front	Standard
Interface, rear	Stub tail
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Total Ports, quantity	24

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in
Cable Stub Length	46 m 150.919 ft

Ordering Tree

FMT-JN2A80460-A24P

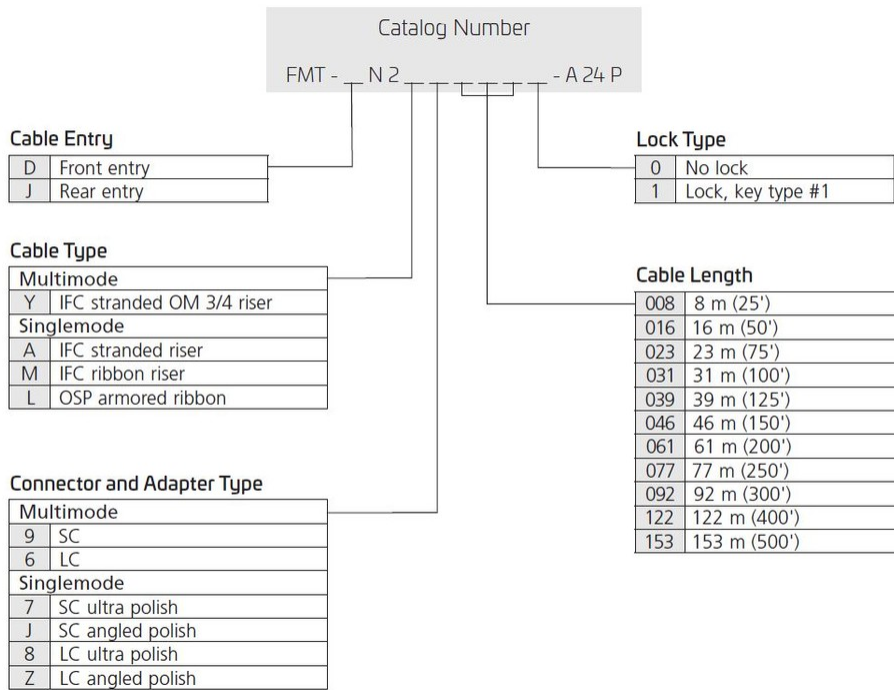

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Packaging and Weights

Packaging quantity	1
---------------------------	---