

# 760027748 | MODG2-12LC-LS-PT



G2 Modular Cassette with 12 LC LazrSPEED® 550 Pigtails

## OBSOLETE

### Replaced By:

760109470 360G2 Multimode OM4 Fiber Cassette 12 LC, with pigtails, iPatch Ready  
360G2 Cartridge 12-LC-LS-AQ-PIGTAILS

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	SYSTIMAX®
<b>Product Type</b>	Fiber cassette with pigtails
<b>Product Brand</b>	LazrSPEED®

## General Specifications

<b>Adapter Color</b>	Aqua
<b>Interface, front</b>	LC/UPC
<b>Interface, rear</b>	Stranded pigtail
<b>Total Fibers, quantity</b>	12
<b>Total Ports, quantity, front</b>	12

## Dimensions

<b>Height</b>	30.48 mm   1.2 in
<b>Width</b>	91.44 mm   3.6 in
<b>Depth</b>	119.38 mm   4.7 in
<b>Pigtail Length</b>	1.5 m   4.921 ft

## Optical Specifications

<b>Fiber Type</b>	OM4, LazrSPEED® 550
<b>Insertion Loss, typical</b>	0.27 dB
<b>Return Loss, minimum</b>	20 dB

## Environmental Specifications

**Safety Standard** UL

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

**Agency**

**Classification**


ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

## Included Products

700207004 – LazrSPEED® LC Multiport Shuttered Adapter, Aqua, Single Pack  
MFA-LC12-AQ-SHUTTERED

# 700207004 | MFA-LC12-AQ-SHUTTERED

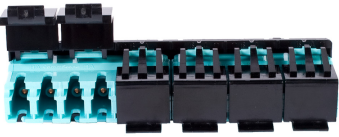

LazrSPEED® LC Multiport Shuttered Adapter, Aqua, Single Pack

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber adapter
<b>Product Brand</b>	LazrSPEED®
<b>Product Series</b>	MFA

## General Specifications

<b>Body Style</b>	Ganged
<b>Color</b>	Aqua
<b>Interface</b>	LC/UPC
<b>Mounting</b>	No flange
<b>Shuttered</b>	Yes
<b>Total Ports, quantity</b>	12

## Material Specifications

<b>Alignment Sleeve Material</b>	Zirconia (ceramic)
----------------------------------	--------------------

## Optical Specifications

<b>Fiber Mode</b>	Multimode
-------------------	-----------

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant

# 700207004 | MFA-LC12-AQ-SHUTTERED

---

UK-ROHS

Compliant

