

760031039 | MODG2-12LC-SM-PT



G2 Modular Cassette with 12 LC TeraSPEED® Singlemode Pigtails

OBSOLETE

Replaced By:

760109496 360G2 Singlemode Fiber Cassette 12 LC, with pigtails, iPatch Ready
360G2 Cartridge 12-LC-SM-BL-PIGTAILS

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Fiber cassette with pigtails
Product Brand	TeraSPEED®

General Specifications

Adapter Color	Blue
Interface, front	LC/UPC
Interface, rear	Stranded pigtail
Total Fibers, quantity	12
Total Ports, quantity, front	12

Dimensions

Height	30.48 mm 1.2 in
Width	91.44 mm 3.6 in
Depth	119.38 mm 4.7 in
Pigtail Length	1.5 m 4.921 ft

Optical Specifications

Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
Insertion Loss, typical	0.3 dB
Return Loss, minimum	55 dB

Environmental Specifications

Safety Standard UL

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

ISO 9001:2015


Classification

Designed, manufactured and/or distributed under this quality management system

Included Products

760049809 – TeraSPEED® LC Multiport Shuttered Adapter, Blue, Single Pack
SFA-LC12-BL-SHUTTERED

760049809 | SFA-LC12-BL-SHUTTERED

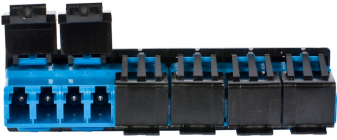

TeraSPEED® LC Multiport Shuttered Adapter, Blue, Single Pack

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber adapter
Product Brand	TeraSPEED®
Product Series	SFA

General Specifications

Body Style	Ganged
Color	Blue
Interface	LC/UPC
Mounting	No flange
Shuttered	Yes
Total Ports, quantity	12

Material Specifications

Alignment Sleeve Material	Zirconia
----------------------------------	----------

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

UK-ROHS

Compliant

