

FL2-C920096PW-8A00

FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 96 FC/UPC, singlemode, 10RU, 19 in, putty white

OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	16
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	FC
Interface Feature, front	Standard
Patching Capacity, maximum	96
Rack Type	EIA 19 in
Rack Units	10
Shelf Movement	Hinged
Splicing Capacity, maximum	96
Total Ports, quantity	96

Dimensions

Height	444.5 mm 17.5 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

FL2-C920096PW-8A00

Ordering Tree

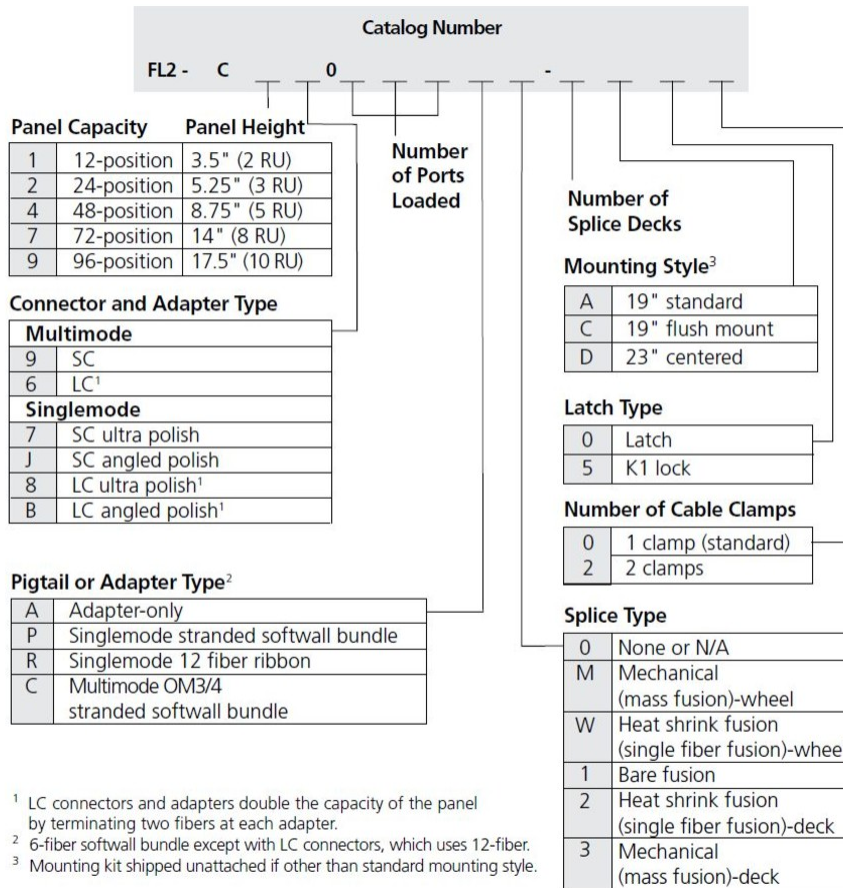

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

FL2-C920096PW-8A00

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

Classification

Above maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant/Exempted

