


FL2-CB60024PN-2A00

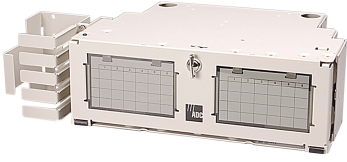

FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 24 LC/UPC, multimode, 3RU, 19 in, putty white

OBSOLETE

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	2
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Color, front	Putty white
Growth Configuration	Partially loaded
Interface, front	LC/UPC
Patching Capacity, maximum	48
Rack Type	EIA 19 in
Rack Units	3
Shelf Movement	Hinged
Splicing Capacity, maximum	48
Total Ports, quantity	24

Dimensions

Height	133.35 mm 5.25 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

FL2-CB60024PN-2A00

Ordering Tree

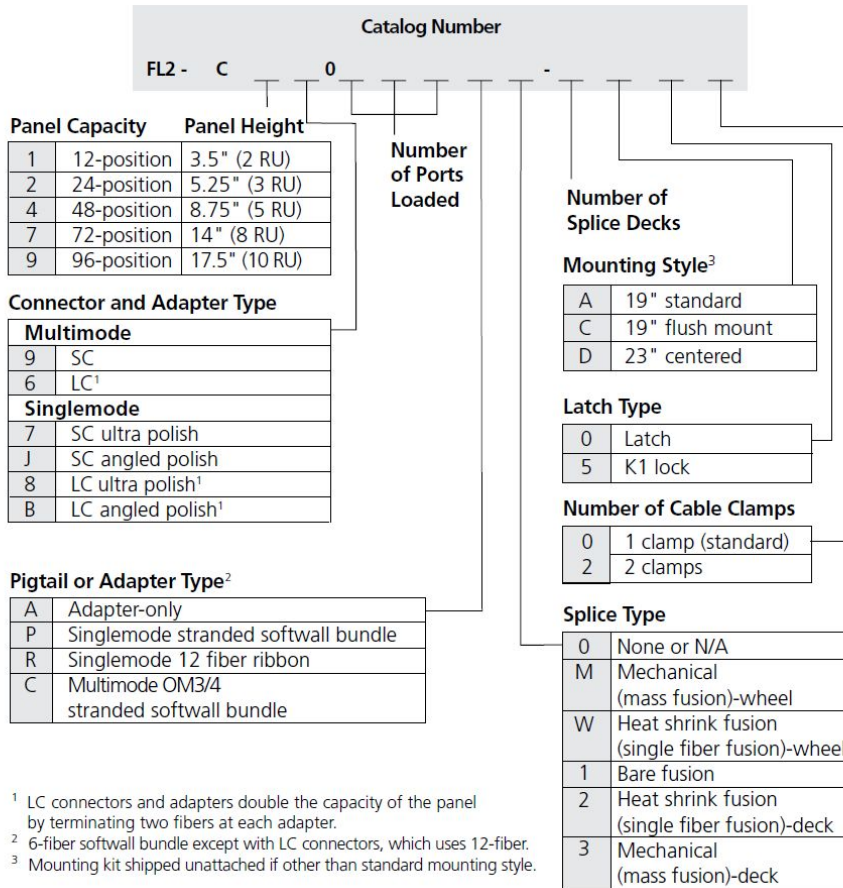

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Multimode
-------------------	-----------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

FL2-CB60024PN-2A00

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant

