


FPCDY-SPSC-P-5M

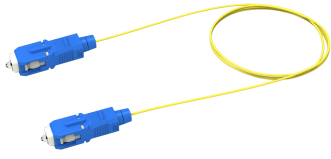

Fiber Optic Patch Cord, Simplex, Singlemode, SC/UPC to SC/UPC, yellow, 5 m

Product Classification

| | |
|------------------------------|-------------------------------|
| Regional Availability | Latin America North America |
| Product Type | Fiber patch cord, simplex |
| Product Series | FPCDY |

General Specifications

| | |
|-------------------------------|--------|
| Connector A, quantity | 1 |
| Color, boot A | Blue |
| Color, connector A | Blue |
| Connector B, quantity | 1 |
| Color, boot B | Blue |
| Color, connector B | Blue |
| Interface, Connector A | SC/UPC |
| Interface, Connector B | SC/UPC |
| Jacket Color | Yellow |
| Total Fibers, quantity | 1 |

Dimensions

| | |
|--------------------|-----------------|
| Cord Length | 5 m 16.404 ft |
|--------------------|-----------------|

Optical Specifications

| | |
|---|----------------------|
| Fiber Mode | Singlemode |
| Fiber Type | G.657.A2, TeraSPEED® |
| Insertion Loss, maximum, connector A | 0.2 dB |
| Insertion Loss, maximum, connector B | 0.2 dB |
| Return Loss, minimum, connector A | 55 dB |
| Return Loss, minimum, connector B | 55 dB |

FPCDY-SPSC-P-5M

Environmental Specifications

Environmental Space Plenum

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Above maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

