

# FLHSTMJAK

---

LazrSPEED® 150 ST to MTRJ, InstaPATCH® 360 Ruggedized Fanout Cable, 72-Fiber, Plenum

**OBSOLETE**

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	SYSTIMAX®
<b>Product Type</b>	Fiber fanout cable assembly
<b>Product Brand</b>	InstaPATCH® 360   LazrSPEED®
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


<b>Color, connector A</b>	Black
<b>Color, connector B</b>	Black
<b>Construction Type</b>	InstaPATCH® 360 ruggedized fanout, indoor
<b>Fibers per Subunit, quantity</b>	12
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	ST/UPC
<b>Interface, Connector B</b>	MTRJ/UPC
<b>Total Fibers, quantity</b>	72

## Dimensions

<b>Cable Assembly Length, minimum (ft)</b>	8
<b>Cable Assembly Length, maximum (ft)</b>	999
<b>Cable Assembly Length, minimum (m)</b>	3
<b>Cable Assembly Length, maximum (m)</b>	999

## Ordering Tree

# FLHSTMJAK

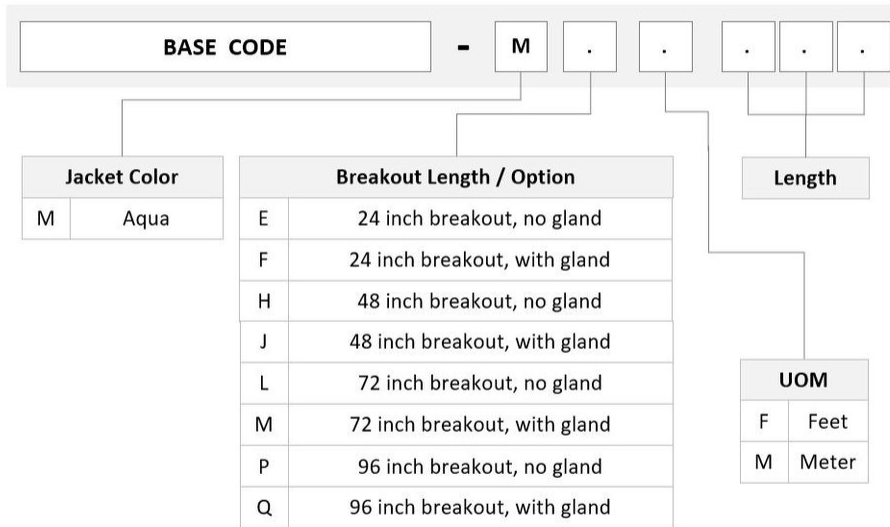

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Type** OM2, bend insensitive

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Plenum

## Regulatory Compliance/Certifications

**Agency**                      **Classification**

# FLHSTMJAK

---

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

