


UPGLCLCCL

Base Product

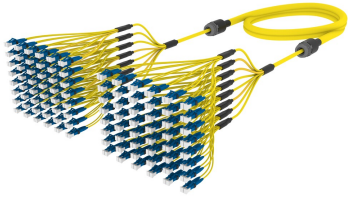

Ultra Low Loss (ULL) Singlemode LC/UPC to LC/UPC Armored Pre-terminated Trunk Cable, 96-Fiber, Dual Rated LSZH/Riser

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity

96

Color, boot A

Blue

Color, connector A

Blue

Connector B, quantity

96

Construction Type

Ultra Low Loss (ULL) armored trunk/extension/cross-connect, indoor

Furcation Color

Yellow

Interface, Connector A

LC/UPC

Interface, Connector B

LC/UPC

Jacket Color

Yellow

Total Fibers, quantity

96

Dimensions

Cable Assembly Length Range (m)


7 – 999

Cable Assembly Length Range (ft)

25 – 999

Ordering Tree

UPGLCLCCL

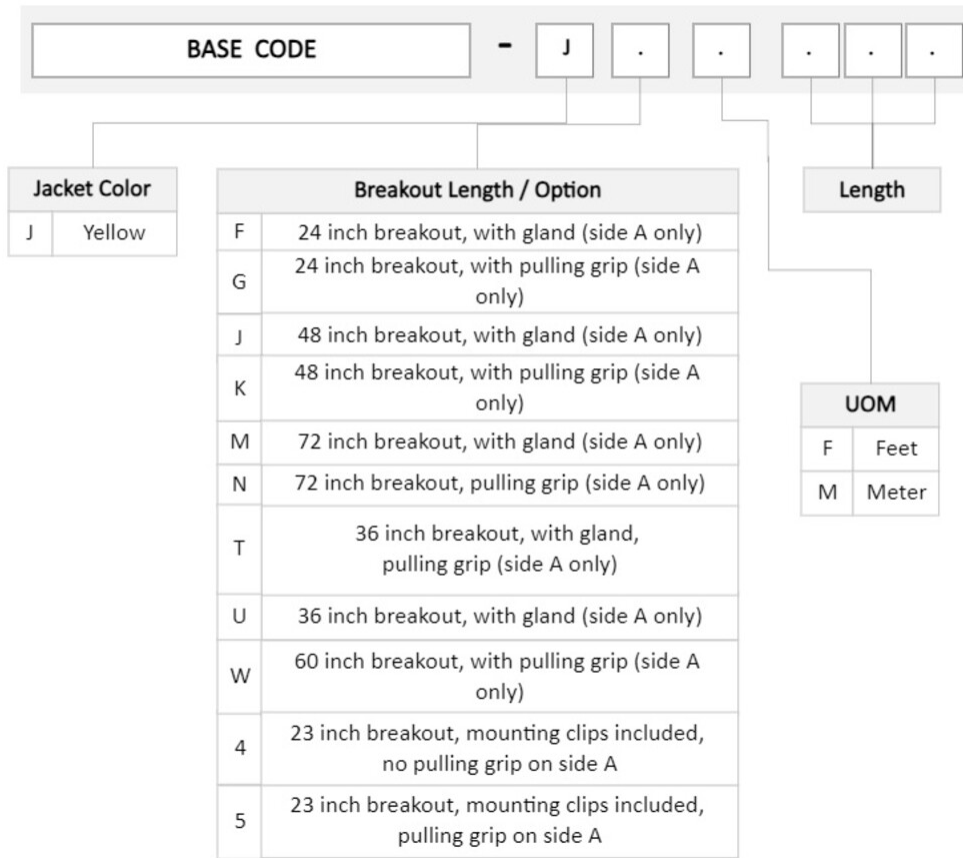

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser Indoor

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

UPGLCLCCL

Included Products

- 760256105
N-096-MZ-8G1-F12YL/20T/B2 – Fiber indoor cable, Riser/LSZH rated MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2/B2, 96 fiber, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860637435 – LC/UPC Connector, Singlemode, Blue, Short Boot