


CX3750003 | 200T040P3875JCASS COEX

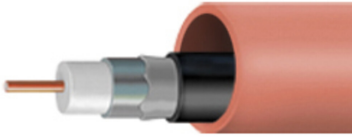

ConQuest® Cable in Conduit, 2 in, SCH 40, terracotta (P3® 875 JCASS)

- *Product complies with the Build America, Buy America Act (BABAA) requirements of the Infrastructure Investment and Jobs Act of 2021 (Pub. L. 117- 58, §§ 70901-70953), or is the subject of a waiver approved by the Secretary of Commerce or designee. Compliance requirements and waiver applicability vary based on government funding program. Check the laws and regulations for your specific program.

Product Classification

Regional Availability	North America
Product Type	Coaxial cable-in-conduit
Product Brand	ConQuest®
Product Series	875 Series
Government Requirements	Build America Buy America (BABA) compliant*

General Specifications

Cable Type	875 Series
Cable-In-Conduit Type	P3® in duct
Color	Terracotta
Conduit Type	Non-toneable
Location of Manufacturing	Catawba, North Carolina
Wall Type	Smooth

Dimensions

Length	762 m 2500 ft
Wall Thickness Designation	SCH 40
Nominal Size	2 in

Packaging and Weights

Weight, net	1,092.312 kg/km 734 lb/kft
--------------------	------------------------------

Included Products

5309103 P3® 875 JCASS	-	75 Ohm P3® Trunk and Distribution Cable, black PE jacket, flooded for underground
--------------------------	---	---

CX3750003 | 200T040P3875JCASS COEX

- 5309193 P3@ 875 JCASS - 75 Ohm P3@ Trunk and Distribution Cable, black PE jacket, flooded for underground
- CX3799999 200T040 EMPTY DUCT COEX - ConQuest@ Empty Conduit, 2 in, SCH 40, terracotta